

Pre-Crimped Leads >

Molex's range of pre-crimped leads offers a simple, cost-effective solution for prototyping, pre-production and mass production requirements. These leads are offered in female-to-female and male-to-male configurations in lengths of 75.00 to 600.00mm.



C-Grid III CLIK-Mate DuraClik iGrid KK KK Plus



Mega-Fit MicroClasp Micro-Fit 3.0 Micro-Fit Plus Micro-Lock Plus Micro-One




Milli-Grid Mini-Fit Mini-Fit Max Mini-Fit Sigma Mini-Fit Sr. Mini-Lock



Mini-Fit Versa Color Mini-SPOX Mizu-P25 MLX MX150 Nano-Fit



OneBlade PicoBlade Pico-Clasp Pico-EZmate Pico-Lock Pico-SPOX

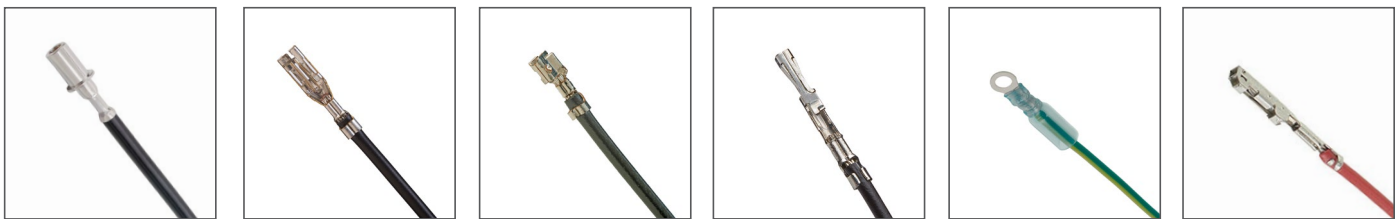

PowerWize Sabre Sherlock SL Solderless Ring Squba

Pre-Crimped Leads



Stac64



Standard .062"



Standard .093"



Ultra-Fit



Zero-Hachi

Ordering Information

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
C-Grid	79758	150, 300	Female	Female	22	UL 1061
CLIK-Mate	79758, 215710, 215711	75, 150, 225, 300, 450	Female, Male	Female, Male	24, 26, 28	UL 1061, UL 10002
DuraClik	79758	150, 300	Female	Female	26	UL 1061
iGrid	217490, 217491	75, 150, 225, 300, 450	Female	Female	22, 24, 26	UL 10002
KK	79758	150, 300	Female, Male	Female, Male	22, 24	UL 1061, UL 1007
KK Plus	79758, 217510, 217511	75, 150, 225, 300, 450	Female	Female	18, 22, 24, 26	UL 1015, UL 1569
Mega-Fit	79758	150, 300	Female	Female	16, 12	UL 1015
Micro-Clasp	79758	150, 300	Female	Female	24	UL 1007
Micro-Fit 3.0	79758, 214760, 214761, 214762, 214763	150, 300, 600	Female, Male	Female, Male	18, 20	UL 1061, UL 10002
Micro-Fit Plus	36769	300	Female, Male	Strip and Tin	16, 20, 24	UL 1061 (16AWG) UL 11028 (20AWG, 24AWG)
Micro-Lock Plus	79758, 217500, 27501	75, 15, 225, 300, 450	Female	Female, Strip	22, 24, 26	UL 1061, UL 10002
Micro-One	219654	75, 150, 225, 300, 450	Female	Female	22	UL 1569
	219655			Strip	22, 24, 26	
Mini-Fit Max	224087 224088	150, 300, and 450	Female	Female	2.00	UL1569

Pre-Crimped Leads



Ordering Information

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
Mini-Fit Sigma	219670 219671	75, 150, 225, 300, 450	Female	Female	16, 18, 20	UL 11028
Mini-Fit Sr.	217480, 217481, 217482, 217483	150, 225, 300, 450	Female, Male	Female, Male	8, 10, 12	UL 10669
Mini-Fit Versa Color	226197	150, 300, 450	Female, Male	Female, Male, Strip and Tin	18, 20	UL 1015
Mini-Lock	79758	150, 300	Female	Female	22	UL 1061
Mini-Spox 2.5	219676 219677	75, 150, 225, 300, 450	Female	Female	22, 24, 26	UL 1569
Mizu-P25	217840, 217841, 217842, 217843, 217520, 217521, 217522, 217523	75, 150, 225, 300, 450	Female, Male	Female, Male	20, 22	UL10002, FLRY-B
MLX	79758	150, 300	Female, Male	Female, Male	18	UL 1015
MX150	216300, 216301, 216302, 216303	150, 225, 300, 450, 600	Female, Male	Female, Male	14, 16, 18	TXL
Nano-Fit	79758	150, 300	Female	Female	20	UL 1061
OneBlade	219674, 219675	150, 300, 450	Female	Female, Strip and Tin	28 30	UL 10125
PicoBlade	79758, 214920, 214921, 214922, 214923	75, 150, 225, 300, 450	Female, Male	Female, Male	26, 28	UL 1061
Pico-Clasp	79758	150, 300	Female	Female	28	UL 1571
Pico-EZmate	79758	300	Female	Female	28	UL 1516
Pico-Lock	79758	150, 300	Female	Female	24, 30	UL 1061, UL 1571
Pico-SPOX	79758	150, 300	Female	Female	24	UL 1061
PowerWize	221960	600	Female	Female	2	UL 10198
			Female	Strip		
Sabre	79758	150, 300	Female, Male	Female, Male	16	UL 1015
Sherlock	79758	150, 300	Female	Female	26	UL 1061

Pre-Crimped Leads



Ordering Information

Product Family	Series Number	Length (mm)	Connector A	Connector B	Wire Size (AWG)	Wire/Cable Type
SL	79758, 219680, 219681	75, 150, 225, 300, 450	Female	Female	22, 24, 26, 28	UL 1061, UL 11028
Squba	217790, 217791, 217792, 217793, 219676, 219677	75, 150, 225, 300, 450	Female	Female	22, 24, 26	UL 10002, UL 1569
Stac64	224451, 224452, 224572	150, 300, 450	Female	Female, Strip	18, 20	FLRYW
Standard .062"	79758	150, 300	Female, Male	Female, Male	22	UL 1015
Standard .093"	79758	150, 300	Female, Male	Female, Male	18	UL 1015
Ultra-Fit	79758, 217470, 217471	75, 150, 225, 300, 450	Female	Female	16, 18, 20	UL 1061, UL 11028
Zero-Hachi	219672, 219673	150, 300, 450	Female	Female, Strip and Tin	28, 30	10064

Product Family	Series Number	Length (mm)	Stud Size	Wire Termination	Wire Size (AWG)	Wire/Cable Type
Solderless Ring Terminal	217851	150	10 (M5)	Blunt cut	16 AWG	UL 1015
		300				
		600				

www.molex.com/link/precrimped.html

Molex is a registered trademark of Molex, LLC in the United States of America and may be registered in other countries; all other trademarks listed herein belong to their respective owners.