


SlimStack Board-to-Board Floating Connectors

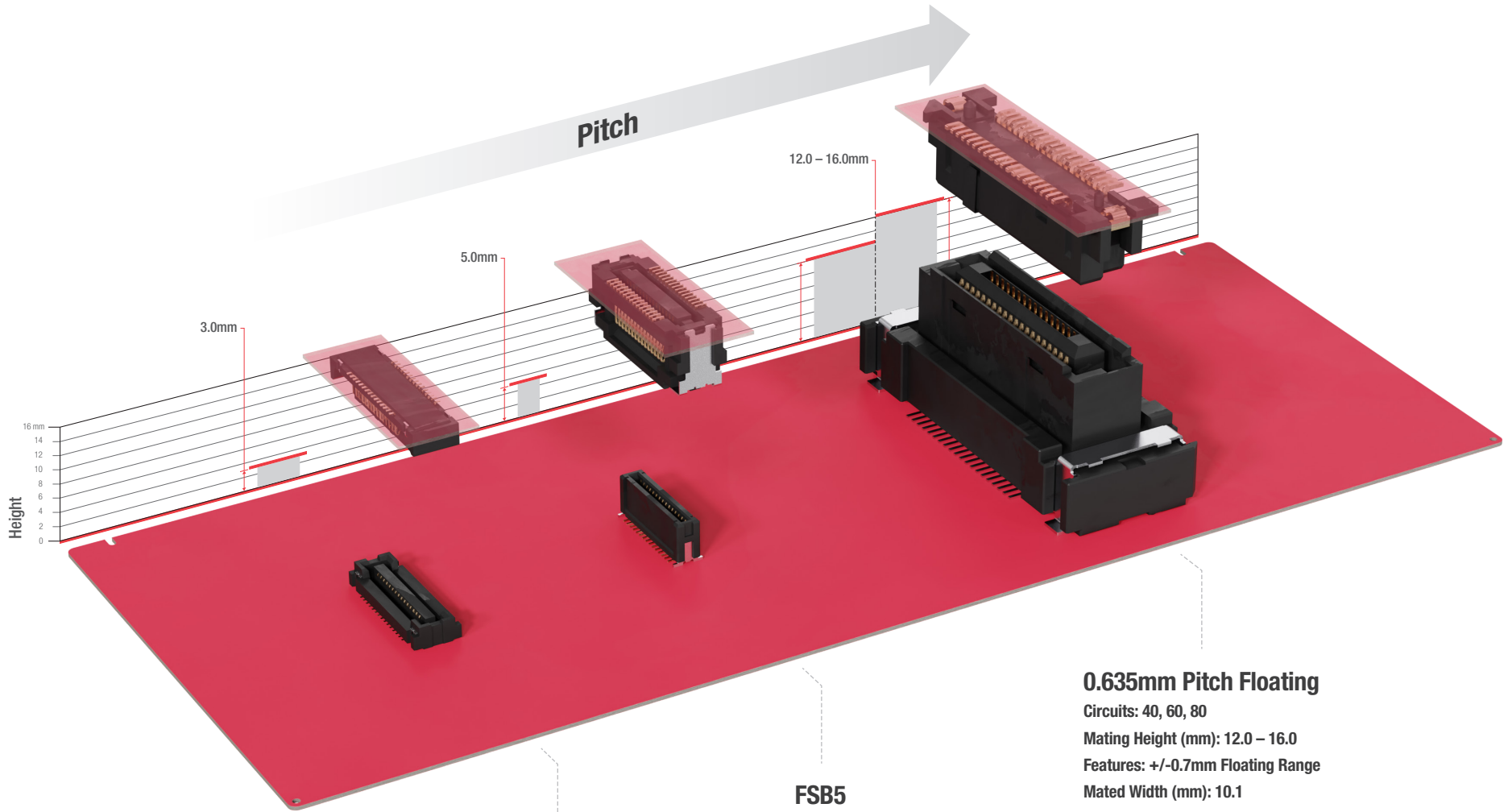

FSB3

Pitch (mm): 0.40
Circuits: 20 to 60
Mating Height (mm): 3.0
Features: +/-0.3mm Floating Range
Mated Width (mm): 3.2

FSB5

Pitch (mm): 0.40
Circuits: 20 to 60
Mating Height (mm): 5.0
Features: +/-0.5mm Floating Range
Mated Width (mm): 3.8

0.635mm Pitch Floating

Circuits: 40, 60, 80
Mating Height (mm): 12.0 – 16.0
Features: +/-0.7mm Floating Range
Mated Width (mm): 10.1