






SOLIDS


- 

1 Protected against a solid object greater than 50mm such as a hand.
- 

2 Protected against a solid object greater than 12.5mm such as a finger.
- 


3 Protected against a solid object greater than 2.5mm such as a screwdriver.
- 


4 Protected against a solid object greater than 1mm such as a wire.
- 


5 Dust protected. Limited ingress of dust permitted. Two to eight hours.
- 


6 Dust tight. No ingress of dust. Two to eight hours.

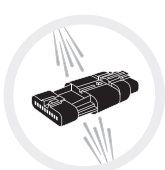
WATER

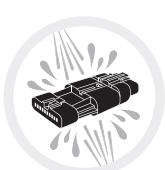
- 

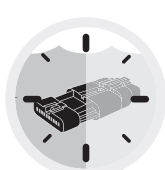
1 Protected against vertical falling drops of water. Limited ingress permitted.
- 

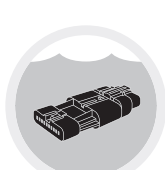
2 Protected against falling drops of water with enclosure tilted up to 15°. Limited water permitted.
- 

3 Protected against sprays of water up to 60° from the vertical. Limited water permitted for three minutes.
- 

4 Protected against water splashed from all directions. Limited water permitted.
- 

5 Protected against currents of water. Limited water permitted.
- 

6 Protected against powerful jets of water. Limited ingress permitted.
- 

7 Protected against the immersion in water between 15cm and 1m for 30 minutes.
- 

8 Can be immersed for long periods of time under water.

IP 67